

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cover profile, for covering terminal strips, snaps onto cover profile carrier AP 3-TU, AP 3-TNS 35, can be marked with insert strip AP-ES. Cover profile carriers should be placed at the ends and at intervals of approx. 40 cm. Length: 1 m

## Commercial data


|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 5022643       |
| Packing unit                         | 14 m          |
| Minimum order quantity               | 1 m           |
| Sales key                            | BE06          |
| Product key                          | BE61ZX        |
| GTIN                                 | 4017918095246 |
| Weight per piece (including packing) | 401.24 g      |
| Weight per piece (excluding packing) | 401.24 g      |
| Customs tariff number                | 39162000      |
| Country of origin                    | DE            |

Technical data

Product properties

|              |               |
|--------------|---------------|
| Product type | Cover profile |
|--------------|---------------|

Dimensions
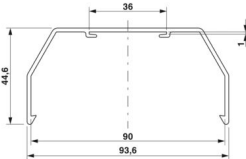
|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 93.5 mm                                                                            |
| Height              | 1000 mm                                                                            |
| Depth               | 44.5 mm                                                                            |
| Length              | 1000 mm                                                                            |


Material specifications

|                                        |             |
|----------------------------------------|-------------|
| Color                                  | transparent |
| Material                               | PVC         |
| Flammability rating according to UL 94 | V0          |

Environmental and real-life conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient conditions              |                  |
| Ambient temperature (operation) | -15 °C ... 65 °C |

## Drawings

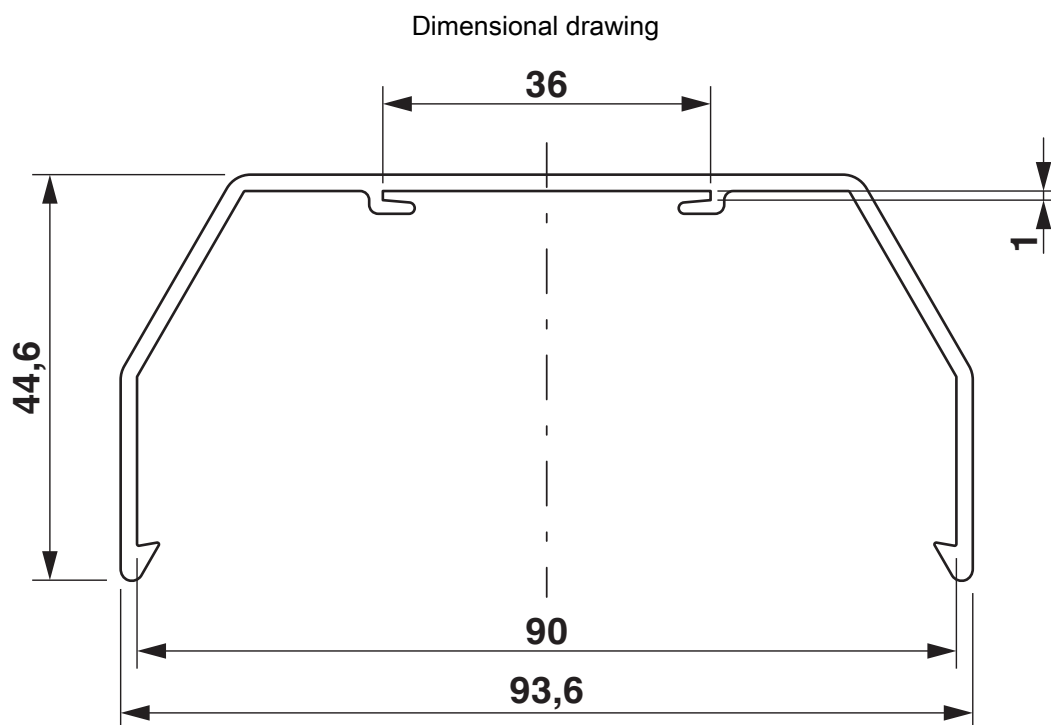

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27141190 |
| ECLASS-15.0 | 27141190 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002848 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

5022643

<https://www.phoenixcontact.com/us/products/5022643>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements

Yes, No exemptions

### China RoHS

Environment friendly use period (EFUP)

EFUP-E

No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)

No substance above 0.1 wt%

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)